



M.O.L.E.® STATUS
 Max Internal T: +52jC
 Battery: 4.540
 Points: 509
 Active: 1X3XXX
 Interval: 00:00:01.0
 Date: 03/17/05
 Time: 09:42:36 V09.02

Tool status box

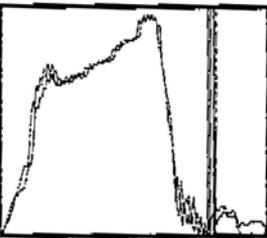

	Zone 1	Zone 2	Zone 3	Zone 4	Zone 5	Zone 6
Temp (C)	17	17	17	17	17	0
Start (s)	250	230	240	250	280	50
End (s)	250	230	240	250	280	50
Count	16.5	Predict	15			

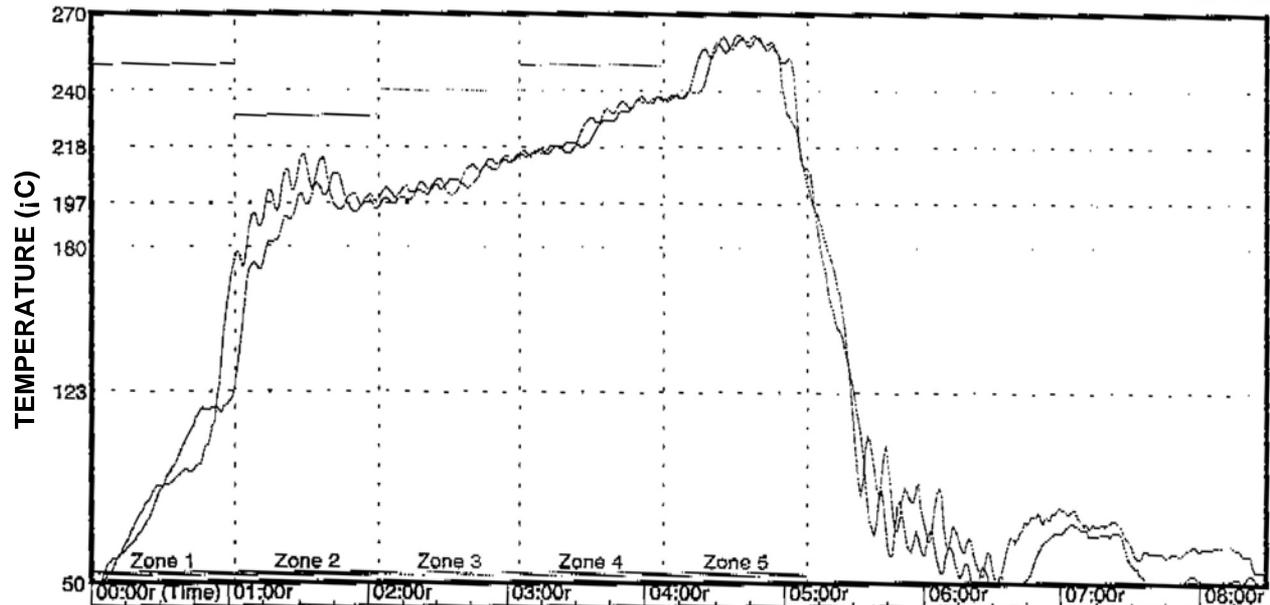

T Above Ref	Low = 180	Med = 218	High = 240	Cure Factor	Units
• Top of Die Upper Left	00:04:11	00:01:40	00:00:41	128%	jC
• Ball of Die Upper Left					
• Top of Die Middle	00:03:59	00:01:46	00:00:43	121%	jC
• Ball of Die Middle					
• Top of Die Lower Right					
• Ball of Die Lower Right					

Summary Stats	Peak	Minimum	Max (+)Slope	Max (-)Slope	Time Above 183C	Time 150C-180C
• Top of Die Upper Left	261.1	37.8	6.67	-8.11	249.0	9.0
• Ball of Die Upper Left						
• Top of Die Middle	262.2	35.0	5.39	-6.28	234.0	10.0
• Ball of Die Middle						
• Top of Die Lower Right						
• Ball of Die Lower Right						
RANGE	1.1	2.8	1.28	1.83	15.0	1.0